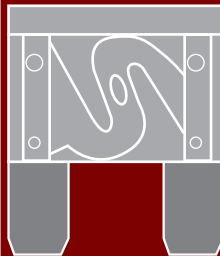
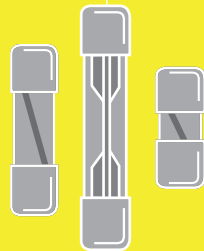
 
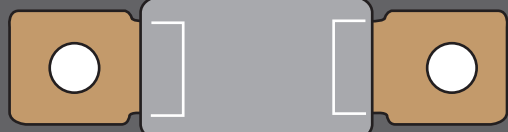


GLASS

AGA	AGC	AGU	AGW	AGX	AGY	SFE	UK
1A 1.5A 2A	.5A 1A 1.5A	1A 2A 3A	1A 1.5A	2A	50A	4A 6A	35A
2.5A 3A 5A	2A 2.5A 3A	4A 5A 10A	2.5A 3A	3A		7.5A 9A	50A
6A 7.5A 10A	4A 5A 6A	15A 20A 25A	4A 5A	20A		14A 20A	
15A 20A 25A	7.5A 8A 10A	30A 35A 40A	6A 15A	25A		30A	
30A	15A 20A 25A	50A 60A	20A 30A	30A			
	30A 35A						

Fuse Selection Chart

FUSE TYPE	ATO®								MINI®				MAXI		GLASS	
ACTUAL FUSE SIZE																
PHOTO																
Series Name	FHAC1	FHAC2	FHA1	FHA2	FHA-GLO	AFH1	AFH1	SEALED ATO	FHM1	FHM2	FHM-GLO	SEALED MINI	MAH1	FNY1	FNY2	
Holder Type	In-Line		In-Line		In-Line	In-Line Panel Mount		In-Line	In-Line		In-Line	In-Line	In-Line	In-Line	In-Line	In-Line
Max Amperage	20A	30A	20A	30A	30A	20A	30A	30A	20A	30A	30A	30A	60A	20A	30A	
Wire Color	Black	Orange	Black	Orange	Red	Black	Red	Red	Black	Orange	Red	Red	Black or Red	Black	Orange	
Weatherproof	•	•			•			•	•	•	•	•	•	•	•	
Notes	Standard	Heavy Duty	Standard	Heavy Duty	Heavy Duty	Standard	Heavy Duty	Heavy Duty	Standard	Heavy Duty	Heavy Duty	Heavy Duty	Standard	Standard	Heavy Duty	

FUSE TYPE	JCASE® and Low Profile JCASE®				MIDI®			MEGA		
ACTUAL FUSE SIZE										
PHOTO										
Series Name	FHJC1	FHJC2	FHJ1	FHJ2	498	Compact-498	FLEX-MIDI	298	SN	FLEX-MEGA
Holder Type	In-Line		In-Line		In-Line	In-Line	Bolt-Down	Bolt-Down	Bolt-Down	Bolt-Down
Max Amperage	40A	60A	40A	60A	200A	200A	200A	500A	500A	500A
Wire Color	Red	Red	Red	Red	–	–	–	–	–	–
Weatherproof	•	•				with heat shrink			•	
Notes	Standard	Heavy Duty	Standard	Heavy Duty	Standard	Compact	Busbars Available	Standard	AssureLatch & IP69K	Busbars Available