

Holder / No. 268

PC Mount, 5x20mm Fuses leadfree

Specifications

Mounting

For direct soldering to PC Boards.
Leads should not be twisted or bent closer than 3mm from the cap.
Sharp bending of the leads can cause mechanical weakness followed by breaking of the leads.

Materials

Holder: Brass, nickel-plated
Axial Leads: Copper, tin-plated for soldering

Electrical Data (23°C)

Rated Voltage: 250V
Maximum Current: 8A

Minimum Cross Section

Conducting path - 0.2mm²

Unit Weight


0.3g

Packaging



Bulk (5000 pcs.)

Order Number

Holder No. 268 0000 100

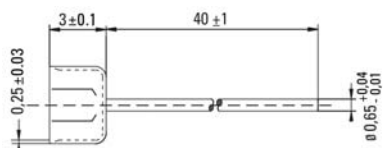

3mm Cap depth

 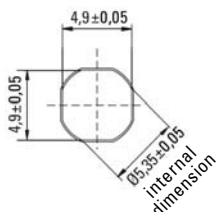

Order Information

Qty.	Order-Number	Series		Packaging
		268	0000	100

Holder / No. 266

PC Mount, 6.3x32mm Fuses leadfree

Specifications

Mounting

For direct soldering to PC Boards.
Leads should not be twisted or bent closer than 3mm from the cap.
Sharp bending of the leads can cause mechanical weakness followed by breaking of the leads.

Materials

Holder: Brass, silver-plated
Axial Leads: Copper, tin-plated for soldering

Electrical Data (23°C)

Rated Voltage: 250V
Maximum Current: 8A

Minimum Cross Section

Conducting path - 0.2mm²

Unit Weight

 


0.4g

Packaging

Bulk (2000 pcs.)

Order Number

Holder No. 266 0000 100

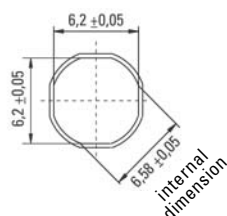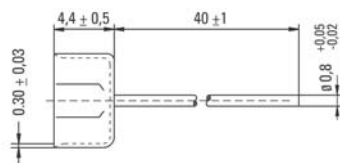

Order Information

Qty.	Order-Number	Series		Packaging
		266	0000	100

Note: 1.00 means the number one with two decimal places. 1,000 means the number one thousand.

Specifications are subject to change without notice.