


# PCB MOUNT FUSE HOLDER FOR MINI® STYLE BLADE FUSE

125Vdc

RoHS

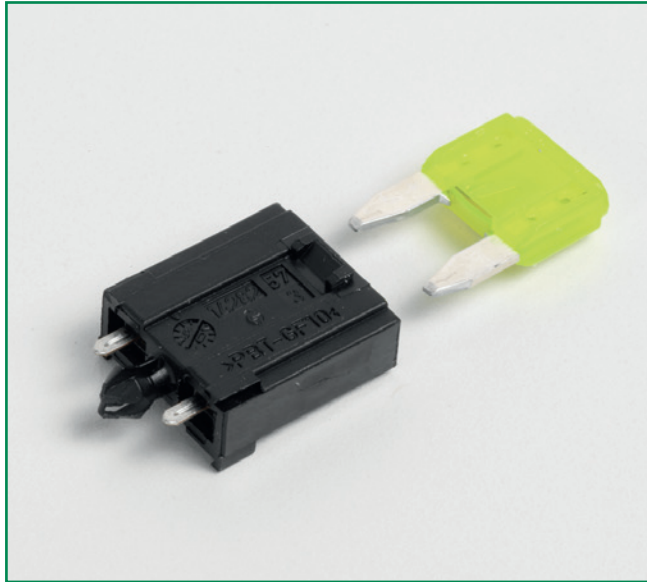

## Specifications

<b>Max Voltage Rating:</b>	125V
<b>Max Current Rating:</b>	30A
<b>Connections:</b>	Leaf spring connector system
<b>Body Material:</b>	Thermoplastic UL 94-V0, heat-resistant
<b>Clip Material:</b>	Copper alloy, Tin-plated finish


## Ordering Information

PART NUMBER	PACKAGE SIZE
178.6764.0001	100

## Description

Fuse holder for MINI/ FK1 fuses for PCB applications. The FL1 Fuse Holder can be mounted in a row of nearly any number. The terminals fit into a 7.62 mm pitch.

## Dimensions in mm

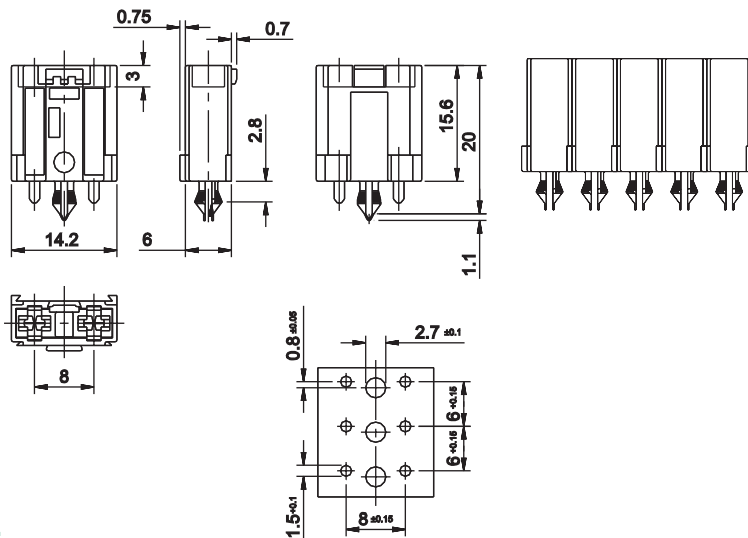

## Ratings

Part Number	Description	Contact Temperature
178.6764.0001	Complete	max. 130°C

The FL1 Fuse Holder can be mounted in a row in nearly any number. The terminals of the holder will also fit into a 7.62 mm pitch.