

ATS In-line Fuse Holder for Torpedo Style Fuse Rated 36V

RoHS



Specifications

- Housing:** Out of thermoplastic (UL 94-V0, heat-resistant)
- Connections:** Squeeze and screw connections for 2.5mm² cable
- Metal parts:** Copper alloy
- Color:** Black
- Packaging:**


Series Serien	Pack Size
276.5105.xxx2	100

ATS Inline holder for Torpedo-style fuse links up to 36V.

In-Line-Sicherungshalter für Torpedo-Sicherungen bis 36V.

Fuse Holders
Inline

Dimensions in mm / Maße in mm

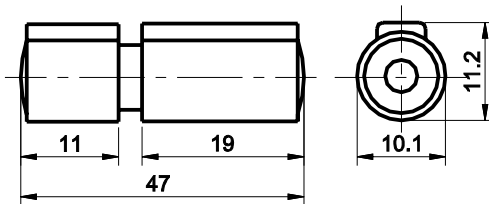

Part Number Artikel-Nr.	Description Beschreibung	Contact Temperature Kontakttemperatur
276.5105.0002	Without fuse link	–
276.5105.4802	With fuse link 8A	–
276.5105.5162	With fuse link 16A	–

Corresponding fuse links see Section “Torpedo Type Fuses.”