


2

1

B

B

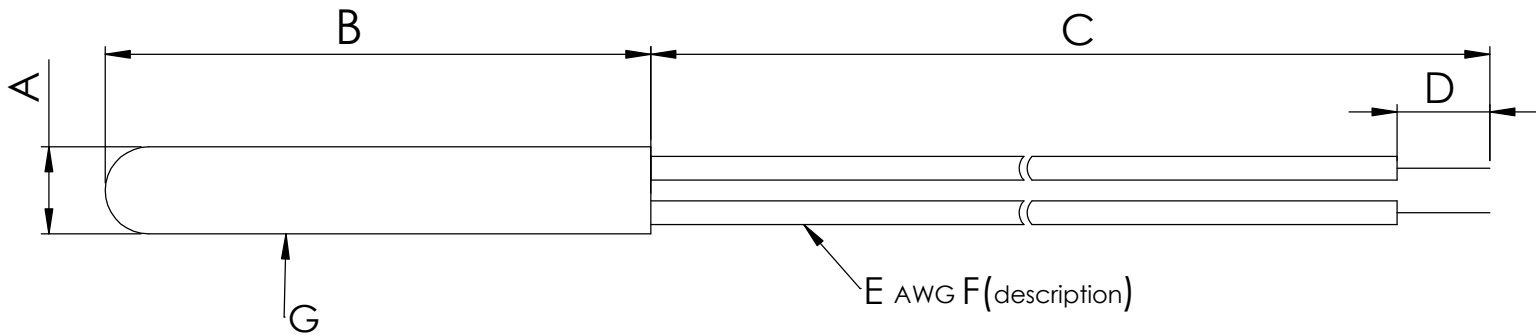

Mechanical Dimensions :

A	B	C	D	E	F	G
0.042" to 0.438" (1.066 to 11.125mm)	0.2" to 36" (5.08 to 914.4 mm)	1" to Custom Lengths (25.4mm to Custom lengths)	0.157" to 0.250" (3.9878 to 6.350mm )	18AWG to 34AWG	Various Cables and Wires	300 Stainless steel series

Electrical Specifications :

Resistance (25 °C) Ω	Resistance Tolerance, ±%	Accuracy ( ± °C)	Temp, Coefficient (%/°C)	Beta(K)	Temp Rating( °C)
1000 Ω to 2000000 Ω	1 to 10	0.1~1	3.31 to 4.4	2000~5000	-40 ~ +300

A

A

Project Code XXXXXX			
Third Angle Projection			
Units Inch(mm)		Division IBU - Temperature Sensors	
General Tolerances 0.X = ± 0.X 0.XX = ± 0.XX 0.XXX = ± 0.XXX		Title Glass Encapsulated NTC Thermistors	
Drawn By RKM		Finished Product Part Number NPSS	
Date 03/28/2023		Internal No. NPSS	
Size A		Do Not Scale	
Sheet 1 of 1		Rev A	

Rev	Description	By	Date	ECO NO
A	Initial Release	RKM	03/28/2023	

Revision History

Reference Legacy No. USPxxxx REV x

2

1